


# Technical data sheet

AML3518 anchor rail, slot 16.5 mm, FS, unperforated

Item number: 1118226

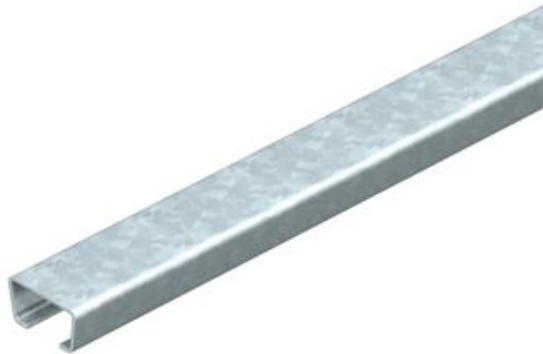

Central C profile rail for cable routing, in conjunction with clamp clips with a hammerhead foot. Can also be used as suspension construction for cable support systems.



|    |                  |
|----|------------------|
| St | Steel            |
| FS | Strip galvanised |

## Master data

|                                    |                           |
|------------------------------------|---------------------------|
| Item number                        | 1118226                   |
| Type                               | AML3518UP2000FS           |
| Description 1                      | Profile rail              |
| Description 2                      | unperforated, slot 16.5mm |
| Manufacturer                       | OBO                       |
| Dimension                          | 2000x35x18                |
| Material                           | Steel                     |
| Surface                            | Strip galvanised          |
| Surface standard                   | DIN EN 10346              |
| Smallest sales unit                | 2                         |
| Unit of quantity                   | Metre                     |
| Weight                             | 90 kg                     |
| Weight unit                        | kg/100 m                  |
| CO2 Footprint (GWP) Cradle-to-Gate | 2,0187 kg CO2e / 1 Meter  |


# Technical data sheet

AML3518 anchor rail, slot 16.5 mm, FS, unperforated

Item number: 1118226



## Dimensions

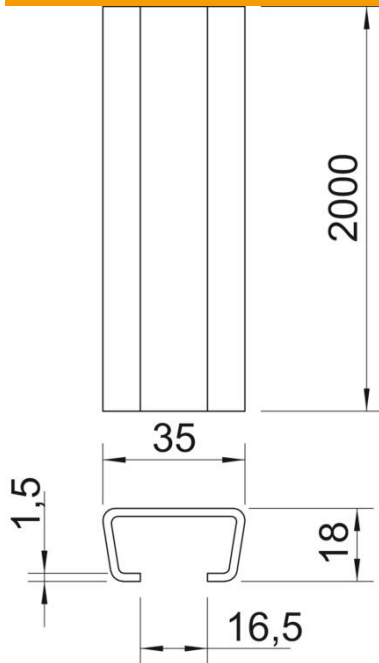

|             |          |
|-------------|----------|
| Length      | 2,000 mm |
| Width       | 35 mm    |
| Height      | 18 mm    |
| Dimension L | 2,000 mm |

## Technical data

|                               |                      |
|-------------------------------|----------------------|
| Breakable                     | no                   |
| Type of perforation           | Without              |
| Version for                   | Single profile       |
| Bundle                        | 20 m                 |
| Maintain electrical functions | no                   |
| Material thickness            | 1.5 mm               |
| With perforation              | no                   |
| With tothing                  | no                   |
| Profile shape                 | C profile            |
| Slot width                    | 16.5 mm              |
| Static value A                | 1.14 cm <sup>2</sup> |
| Static value I <sub>y</sub>   | 0.49 cm <sup>4</sup> |
| Static value I <sub>z</sub>   | 0.85 cm <sup>4</sup> |
| Static value W <sub>y</sub>   | 0.44 cm <sup>3</sup> |
| Static value W <sub>z</sub>   | 1.05 cm <sup>3</sup> |