

Technical data sheet

Mounting rail MS4022, heavy-duty, slot 18 mm, A4, perforated

Item number: 1121903



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



A4	Stainless steel
2B	Bright, treated

Master data

Item number	1121903
Type	MS4022P6000A4
Description 1	Profile rail
Description 2	perforated, slot 18mm
Manufacturer	OBO
Dimension	6000x40x22,5
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	6
Unit of quantity	Metre
Weight	147.6 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,0719 kg CO2e / 1 Meter


Technical data sheet

Mounting rail MS4022, heavy-duty, slot 18 mm, A4, perforated

Item number: 1121903



Dimensions

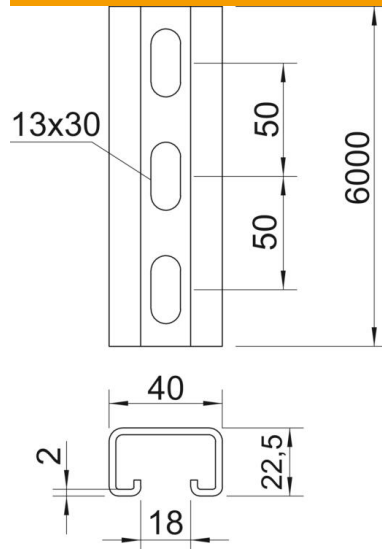

Length	6,000 mm
Width	40 mm
Height	22.5 mm
Dimension L	6,000 mm

Technical data

Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	50 mm
Material thickness	2 mm
With perforation	no
With toothing	no
Profile shape	C profile
Slot width	18 mm
Static value A	1.74 cm ²
Static value I _y	1.86 cm ⁴
Static value I _z	4.46 cm ⁴
Static value W _y	1.05 cm ³
Static value W _z	2.23 cm ³