

# Technical data sheet

Mounting rail MS4022, heavy-duty, slot 18 mm, A4, perforated

Item number: 1121963



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



|    |                 |
|----|-----------------|
| A4 | Stainless steel |
| 2B | Bright, treated |

## Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 1121963                  |
| Type                               | MS4022P2000A4            |
| Description 1                      | Profile rail             |
| Description 2                      | perforated, slot 18mm    |
| Manufacturer                       | OBO                      |
| Dimension                          | 2000x40x22,5             |
| Material                           | Stainless steel 1.4571   |
| Surface                            | Bright, treated          |
| Surface standard                   |                          |
| Smallest sales unit                | 2                        |
| Unit of quantity                   | Metre                    |
| Weight                             | 147.6 kg                 |
| Weight unit                        | kg/100 m                 |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0204 kg CO2e / 1 Meter |


# Technical data sheet

Mounting rail MS4022, heavy-duty, slot 18 mm, A4, perforated

Item number: 1121963



## Dimensions

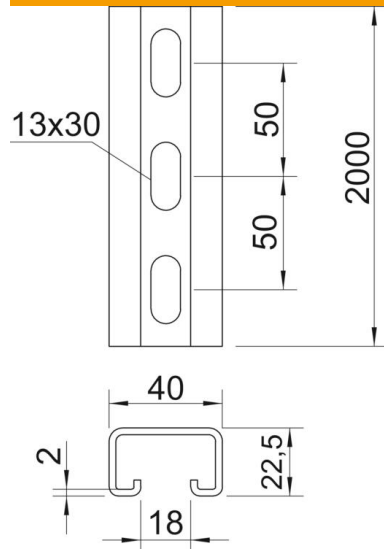

|             |          |
|-------------|----------|
| Length      | 2,000 mm |
| Width       | 40 mm    |
| Height      | 22.5 mm  |
| Dimension L | 2,000 mm |

## Technical data

|                             |                      |
|-----------------------------|----------------------|
| Type of perforation         | Perforated back      |
| Version for                 | Single profile       |
| Drill hole spacing, centre  | 50 mm                |
| Material thickness          | 2 mm                 |
| With perforation            | no                   |
| With tothing                | no                   |
| Profile shape               | C profile            |
| Slot width                  | 18 mm                |
| Static value A              | 1.74 cm <sup>2</sup> |
| Static value I <sub>y</sub> | 1.86 cm <sup>4</sup> |
| Static value I <sub>z</sub> | 4.46 cm <sup>4</sup> |
| Static value W <sub>y</sub> | 1.05 cm <sup>3</sup> |
| Static value W <sub>z</sub> | 2.23 cm <sup>3</sup> |