

Technical data sheet

MS4182 mounting rail, slot 22 mm, double, FS, perforated

Item number: 1122678



Heavy-duty profile/mounting rail with continuous perforation in base, slot width 22 mm. Double version, i.e. two profile rails are interconnected on the base (clinched).



St	Steel
FS	Strip galvanised

Master data

Item number	1122678
Type	MS4182P6000FS
Description 1	Profile rail
Description 2	perforated, slot 22mm
Manufacturer	OBO
Dimension	6000x41x82
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	6
Unit of quantity	Metre
Weight	402.2 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	9,7027 kg CO2e / 1 Meter


Technical data sheet

MS4182 mounting rail, slot 22 mm, double, FS, perforated

Item number: 1122678



Dimensions

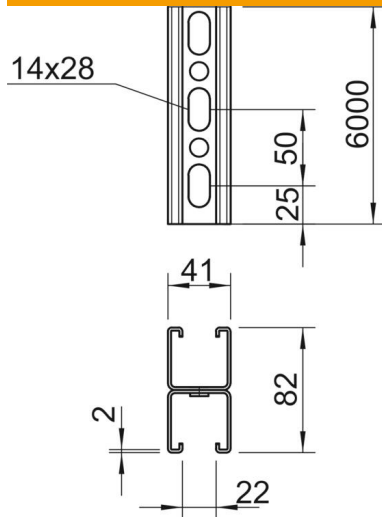

Length	6,000 mm
Width	41 mm
Height	82 mm
Dimension L	6,000 mm

Technical data

Breakable	no
Type of perforation	Perforated bar
Version for	Double profile
Maintain electrical functions	no
Hole size	14x28
Material thickness	2 mm
With toothing	yes
Profile shape	C profile
ROHS-conformant	yes
Slot width	22 mm
Static value A	4.86 cm ²
Static value I _y	30.69 cm ⁴
Static value I _z	15.11 cm ⁴
Static value W _y	2.51 cm ³
Static value W _z	2.69 cm ³