

Technical data sheet

MS4142 mounting rail, slot 22 mm, double, FS, perforated

Item number: 1122947



Heavy-duty profile/mounting rail with continuous perforation in base, slot width 22 mm. Double version, i.e. two profile rails are interconnected on the base (clinched).



St	Steel
FS	Strip galvanised

Master data

Item number	1122947
Type	MS4142P3000FS
Description 1	Profile rail
Description 2	perforated, slot 22mm
Manufacturer	OBO
Dimension	3000x41x42
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	3
Unit of quantity	Metre
Weight	303 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	6,8549 kg CO2e / 1 Meter


Technical data sheet

MS4142 mounting rail, slot 22 mm, double, FS, perforated

Item number: 1122947



Dimensions

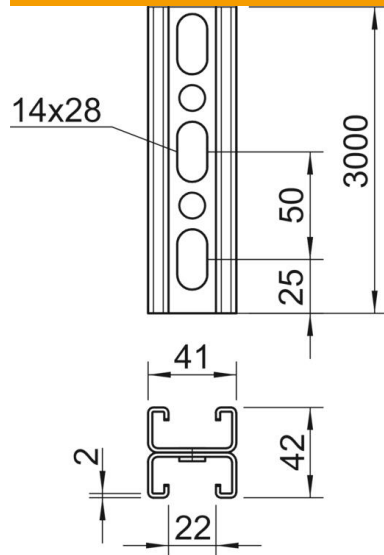

Length	3,000 mm
Width	41 mm
Height	42 mm
Dimension L	3,000 mm

Technical data

Breakable	no
Type of perforation	Perforated bar
Version for	Double profile
Maintain electrical functions	no
Hole size	14x28
Material thickness	2 mm
With tothing	yes
Profile shape	C profile
ROHS-conformant	yes
Slot width	22 mm
Static value A	3.3 cm ²
Static value I _y	5.38 cm ⁴
Static value I _z	9.02 cm ⁴
Static value W _y	1.28 cm ³
Static value W _z	0.25 cm ³