

Technical data sheet

MS4141 mounting rail, slot 22 mm, A2, side perforation

Item number: 1123014



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	1123014
Type	MSL4141PP1000A2
Description 1	Profile rail
Description 2	perforated, slot 22mm
Manufacturer	OBO
Dimension	1000x41x41
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Metre
Weight	179.4 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	10,1491 kg CO2e / 1 Meter


Technical data sheet

MS4141 mounting rail, slot 22 mm, A2, side perforation

Item number: 1123014



Dimensions

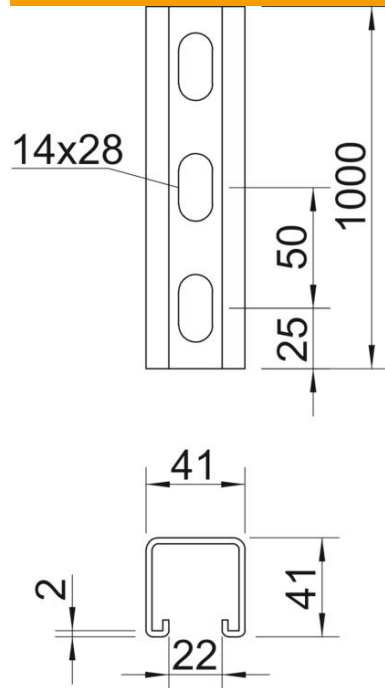

Length	1,000 mm
Width	41 mm
Height	41 mm
Dimension L	1,000 mm

Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
Drill hole spacing, centre	50 mm
Maintain electrical functions	no
Hole size	14x28
Material thickness	2 mm
With perforation	yes
With toothing	yes
Profile shape	C profile
ROHS-conformant	yes
Slot width	22 mm
Static value A	2.01 cm ²
Static value Iy	5.13 cm ⁴
Static value Iz	5.88 cm ⁴
Static value Wy	2.51 cm ³
Static value Wz	2.69 cm ³