

Technical data sheet

MS4141 mounting rail, slot 22 mm, A4, perforated

Item number: 1123049



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



A4	Stainless steel
2B	Bright, treated

Master data		
Item number	1123049	
Type	MS4141P3000A4	
Description 1	Profile rail	
Description 2	perforated, slot 22mm	
Manufacturer	OBO	
Dimension	3000x41x41	
Material	Stainless steel 1.4571	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	3	
Unit of quantity	Metre	
Weight	247.5 kg	
Weight unit	kg/100 m	
CO2 Footprint (GWP) Cradle-to-Gate	12,5263 kg CO2e / 1 Meter	



Technical data sheet

MS4141 mounting rail, slot 22 mm, A4, perforated

Item number: 1123049



Dimensions

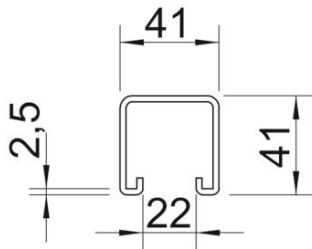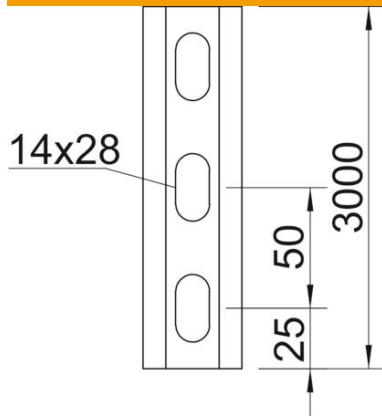

Length	3,000 mm
Width	41 mm
Height	41 mm
Dimension L	3,000 mm

Technical data

Breakable	no
Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	50 mm
Maintain electrical functions	no
Hole size	14x28
Material thickness	2.5 mm
With tothing	yes
Profile shape	C profile
ROHS-conformant	yes
Slot width	22 mm
Static value A	2.97 cm ²
Static value Iy	6.05 cm ⁴
Static value Iz	9.01 cm ⁴
Static value Wy	2.91 cm ³
Static value Wz	4.4 cm ³