


Technical data sheet

Connection plate with 4 holes FT

Item number: 1124649



Connection plate with four holes for straight connection of profile rails 41 x 41 mm and 41 x 21 mm.

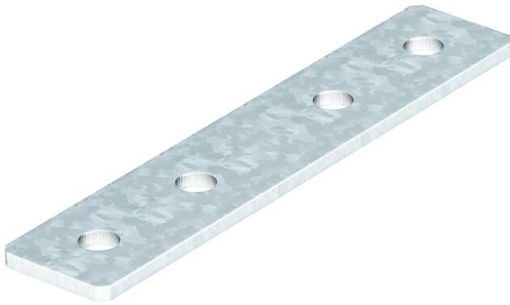

St Steel

FT Hot-dip galvanised

Master data

Item number	1124649
Type	GMS 4 VP FT
Description 1	Connection plate
Description 2	with 4 holes
Manufacturer	OBO
Dimension	200x40x5
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	35.58 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,7485 kg CO2e / 1 Piece


Technical data sheet

Connection plate with 4 holes FT

Item number: 1124649



Dimensions

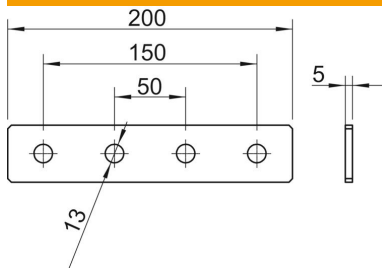

Length	200 mm
Width	40 mm
Height	5 mm

Technical data

Version for	With continuous perforation 13 mm
Version for	Internal connector
Suitable for profile shapes	C profile
Hole size	13
Material thickness	5 mm
With screw accessories	no
ROHS-conformant	yes
Rustproof steel, pickled	no