


Technical data sheet

Connection plate, X-shaped FT

Item number: 1124657



Connection plate with five holes for cross connection of profile rails 41 x 41 mm and 41 x 21 mm.

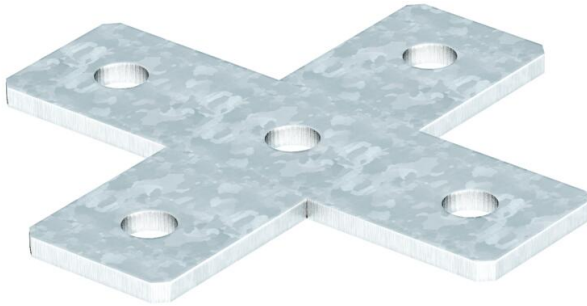

St	Steel
FT	Hot-dip galvanised

Master data

Item number	1124657
Type	GMS 5 VP X FT
Description 1	Connection plate
Description 2	X shape
Manufacturer	OBO
Dimension	150x150x40x5
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	48 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,5397 kg CO2e / 1 Piece


Technical data sheet

Connection plate, X-shaped FT

Item number: 1124657



Dimensions

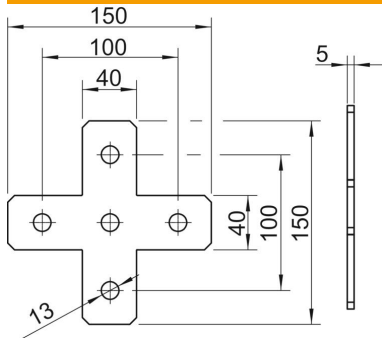

Length	150 mm
Width	40 mm
Height	5 mm

Technical data

Version for	With continuous perforation 13 mm
Version for	Cross-connectors
Suitable for profile shapes	C profile
Hole size	13
Material thickness	5 mm
With screw accessories	no
ROHS-conformant	yes
Rustproof steel, pickled	no