

Technical data sheet

Connection plate with 3 holes A2

Item number: 1124687



Connection plate with three holes for straight connection of profile rails 41 x 41 mm and 41 x 21 mm.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	1124687
Type	GMS 3 VP A2
Description 1	Connection plate
Description 2	with 3 holes
Manufacturer	OBO
Dimension	150x40x4
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	17.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,8254 kg CO2e / 1 Piece


Technical data sheet

Connection plate with 3 holes A2

Item number: 1124687



Dimensions

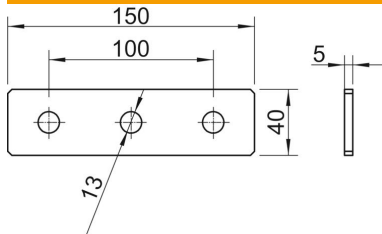

Length	150 mm
Width	40 mm
Height	4 mm

Technical data

Version for	With continuous perforation 13 mm
Version for	Internal connector
Suitable for profile shapes	C profile
Hole size	13
Material thickness	4 mm
With screw accessories	no
ROHS-conformant	yes
Rustproof steel, pickled	no