

Technical data sheet

Connection plate with 2 holes A4

Item number: 1124725



Connection plate with two holes for straight connection of profile rails 41 x 41 mm and 41 x 21 mm.



A4 Stainless steel

2B Bright, treated

Master data

Item number	1124725
Type	GMS 2 VP A4
Description 1	Connection plate
Description 2	with 2 holes
Manufacturer	OBO
Dimension	100x40x4
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	11.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,5529 kg CO2e / 1 Piece


Technical data sheet

Connection plate with 2 holes A4

Item number: 1124725



Dimensions

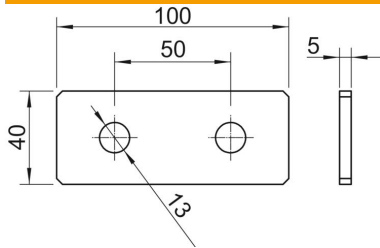

Length	100 mm
Width	40 mm
Height	4 mm

Technical data

Version for	With continuous perforation 13 mm
Version for	Internal connector
Suitable for profile shapes	C profile
Hole size	13
Material thickness	4 mm
With screw accessories	no
ROHS-conformant	yes
Rustproof steel, pickled	no