

# Technical data sheet

## Connection plate with 4 holes A4

Item number: 1124729



Connection plate with four holes for straight connection of profile rails 41 x 41 mm and 41 x 21 mm.



|    |                 |
|----|-----------------|
| A4 | Stainless steel |
| 2B | Bright, treated |

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 1124729                  |
| Type                               | GMS 4 VP A4              |
| Description 1                      | Connection plate         |
| Description 2                      | with 4 holes             |
| Manufacturer                       | OBO                      |
| Dimension                          | 200x40x4                 |
| Material                           | Stainless steel 1.4571   |
| Surface                            | Bright, treated          |
| Surface standard                   |                          |
| Smallest sales unit                | 10                       |
| Unit of quantity                   | Piece                    |
| Weight                             | 23.3 kg                  |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,1246 kg CO2e / 1 Piece |


# Technical data sheet

## Connection plate with 4 holes A4

Item number: 1124729



### Dimensions

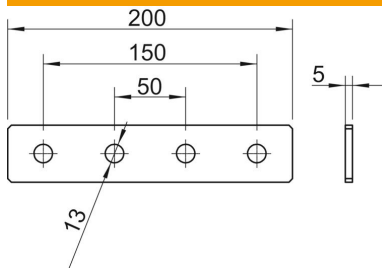

|        |        |
|--------|--------|
| Length | 200 mm |
| Width  | 40 mm  |
| Height | 4 mm   |

### Technical data

|                             |                                   |
|-----------------------------|-----------------------------------|
| Version for                 | With continuous perforation 13 mm |
| Version for                 | Internal connector                |
| Suitable for profile shapes | C profile                         |
| Hole size                   | 13                                |
| Material thickness          | 4 mm                              |
| With screw accessories      | no                                |
| Rustproof steel, pickled    | no                                |