


# Technical data sheet

## Hammer-head bolt

Item number: 1148024



Hammer-head bolt for use with CL2712 profile rail

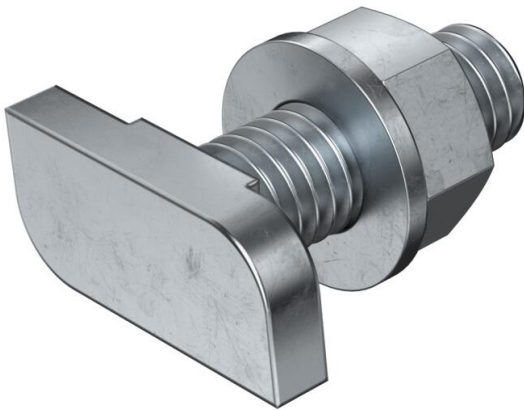

|    |           |
|----|-----------|
| St | Steel     |
| ZL | Zinc slat |

### Master data

|                                    |                         |
|------------------------------------|-------------------------|
| Item number                        | 1148024                 |
| Type                               | CL27HB M6x25 ZL         |
| Description 1                      | Hammerhead screw        |
| Description 2                      | for profile rail CL2712 |
| Manufacturer                       | OBO                     |
| Dimension                          | M6x25mm                 |
| Material                           | Steel                   |
| Surface                            | Zinc slat               |
| Surface standard                   |                         |
| Smallest sales unit                | 50                      |
| Unit of quantity                   | Piece                   |
| Weight                             | 1.57 kg                 |
| Weight unit                        | kg/100 pc.              |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,042 kg CO2e / 1 Piece |


# Technical data sheet

## Hammer-head bolt


Item number: 1148024



### Dimensions

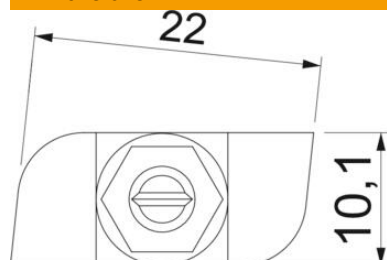

|        |         |
|--------|---------|
| Length | 23 mm   |
| Width  | 10.1 mm |
| Height | 4 mm    |

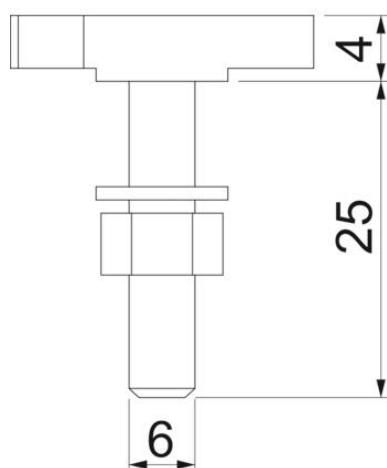

### Technical data

|                            |            |
|----------------------------|------------|
| Suitable for mounting rail | yes        |
| Thread                     | M 6 x 25mm |
| Thread metric              | 6          |