

# Technical data sheet

## Spacer clip 732 G

Item number: 1362408



Spacer clip for the installation of pipes and cables on walls, ceilings and floors. With self-locking cover. Fastening via attachment piece with internal thread.

Approved for the maintenance of electrical function according to DIN 4102 Part 12, maintenance of electrical function classes E 30 to E 90.



St

Steel

G

Electrogalvanised

### Master data

|                                    |                             |
|------------------------------------|-----------------------------|
| Item number                        | 1362408                     |
| Type                               | ASG 732 8 G                 |
| Description 1                      | Distance saddle             |
| Description 2                      | with threaded connection M6 |
| Manufacturer                       | OBO                         |
| Dimension                          | 7-8mm                       |
| Material                           | Steel                       |
| Surface                            | Electrogalvanised           |
| Surface standard                   | EN ISO 19598 / EN ISO 4042  |
| Smallest sales unit                | 25                          |
| Unit of quantity                   | Piece                       |
| Weight                             | 1.2 kg                      |
| Weight unit                        | kg/100 pc.                  |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,048 kg CO2e / 1 Piece     |


# Technical data sheet

## Spacer clip 732 G

Item number: 1362408



### Dimensions

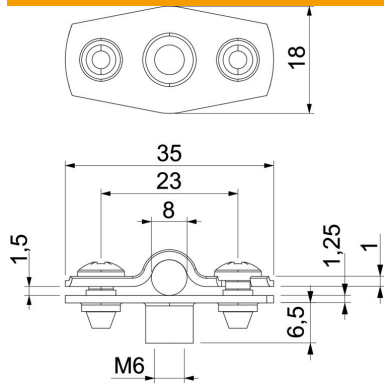

|                   |         |
|-------------------|---------|
| Dimension A       | 35 mm   |
| Dimension B       | 23 mm   |
| Dimension D       | 8 mm    |
| Dimension d max.  | 8 mm    |
| Dimension d min.  | 7 mm    |
| Dimension t1 (mm) | 1 mm    |
| Dimension t2 (mm) | 1.25 mm |
| Dimension x       | 1.5 mm  |

### Technical data

|                               |                     |
|-------------------------------|---------------------|
| Distance to the wall          | yes                 |
| Number of cables/pipes        | 1                   |
| Version for                   | Closed              |
| Fastening type                | Threaded connection |
| Maintain electrical functions | yes                 |
| For diameter                  | 7 - 8               |
| Halogen-free                  | yes                 |
| Plastic-covered               | no                  |
| Material thickness            | 1.25 mm             |
| ROHS-conformant               | yes                 |
| Clamping range D, max.        | 8 mm                |
| Clamping range D, min.        | 7 mm                |
| UV-resistant                  | yes                 |