

Technical data sheet

Spacer clip 732 A2

Item number: 1362634



Spacer clip for the installation of pipes and cables on walls, ceiling and floors.
With self-locking upper part.
Approved for the maintenance of electrical function according to DIN 4102 Part 12, maintenance of electrical function classes E30 to E90.



A2 Stainless steel

Master data		
Item number	1362634	
Type	ASG 732 17 A2	
Description 1	Distance saddle	
Description 2	with threaded connection M6	
Manufacturer	OBO	
Dimension	14-17mm	
Material	Stainless steel 1.4301	
Smallest sales unit	25	
Unit of quantity	Piece	
Weight	2.007 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1916 kg CO2e / 1 Piece	


Technical data sheet

Spacer clip 732 A2

Item number: 1362634



Dimensions

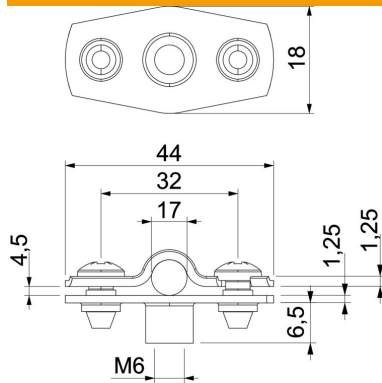

Dimension A	44 mm
Dimension B	32 mm
Dimension b	18 mm
Dimension D	17 mm
Dimension d max.	17 mm
Dimension d min.	14 mm
Dimension H1	12 mm
Dimension t1 (mm)	1.25 mm
Dimension t2 (mm)	1.25 mm
Dimension x	4.5 mm

Technical data

Distance to the wall	yes
Number of cables/pipes	1
Version for	Closed
Maintain electrical functions	yes
For diameter	14 - 17
Halogen-free	yes
Plastic-covered	no
Material thickness	1.25 mm
Clamping range D, max.	17 mm
Clamping range D, min.	14 mm
UV-resistant	yes