

Technical data sheet

Spacer clip 733 A2

Item number: 1362984



Spacer clip for the installation of pipes and cables on walls, ceilings and floors.
With self-locking cover. Fastening via slot.

Approved for the maintenance of electrical function according to DIN 4102 Part 12, maintenance of electrical function classes E 30 to E 90.



A2 Stainless steel

Master data		
Item number	1362984	
Type	ASL 733 20 A2	
Description 1	Distance saddle	
Description 2	with slot	
Manufacturer	OBO	
Dimension	17-20mm	
Material	Stainless steel 1.4301	
Smallest sales unit	25	
Unit of quantity	Piece	
Weight	2.213 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1667 kg CO2e / 1 Piece	


Technical data sheet

Spacer clip 733 A2

Item number: 1362984



Dimensions

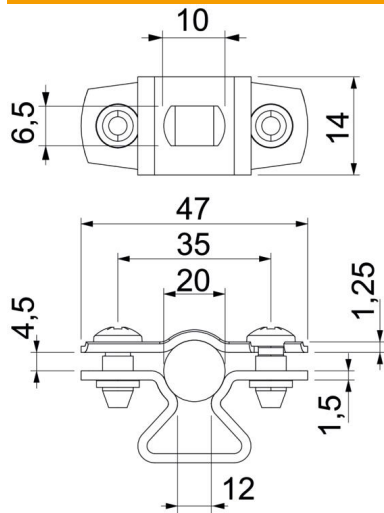

Dimension A	47 mm
Dimension B	35 mm
Dimension b	14 mm
Dimension d max.	20 mm
Dimension d min.	17 mm
Dimension L	10 mm
Dimension s	12 mm
Dimension t1 (mm)	1.25 mm
Dimension t2 (mm)	1.5 mm
Dimension x	4.5 mm

Technical data

Distance to the wall	yes
Number of cables/pipes	1
Version for	Closed
Maintain electrical functions	yes
For diameter	17 - 20
Halogen-free	yes
Plastic-covered	no
Material thickness	1.5 mm
ROHS-conformant	yes
Clamping range D, max.	20 mm
Clamping range D, min.	17 mm
UV-resistant	yes