


Technical data sheet

Screw-in spacer clip

Item number: 1366122

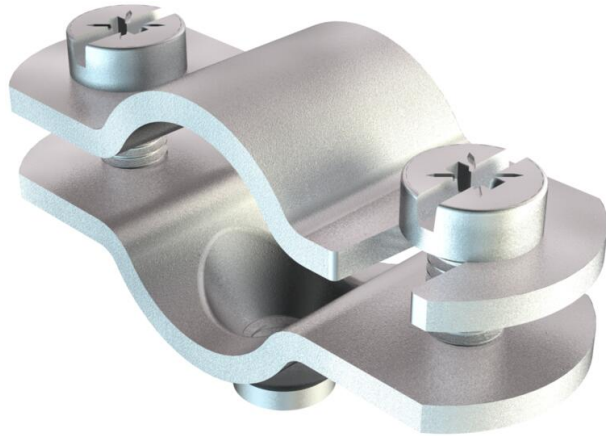

With M6 thread.



St Steel

G Electrogalvanised

Master data

Item number	1366122
Type	731 W 12 G
Description 1	Distance saddle
Description 2	with threaded connection M6
Manufacturer	OBO
Dimension	8-12mm
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	50
Unit of quantity	Piece
Weight	2.47 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0598 kg CO2e / 1 Piece


Technical data sheet

Screw-in spacer clip

Item number: 1366122



Dimensions

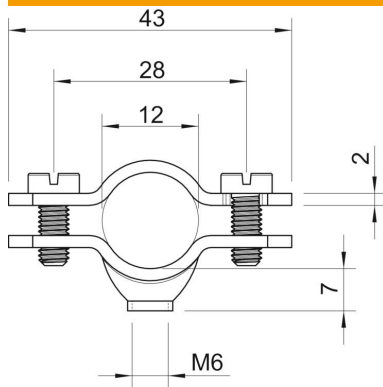

Length	43 mm
Dimension A	43 mm
Dimension B	28 mm
Dimension D	12 mm
Dimension d min.	12 mm
Dimension t	2 mm

Technical data

Number of cables/pipes	1
Version for	Closed
Fastening type	Screw hole
Suitable in fire protection area	no
Halogen-free	no
Plastic-covered	no
Hole size	M6
Material thickness	2 mm
ROHS-conformant	yes
Bolt	M5 x 12
Clamping range D, max.	12 mm
Clamping range D, min.	8 mm
UV-resistant	yes