

Technical data sheet

Screw-in spacer clip 705, double

Item number: 1371207



With M6 thread.



St	Steel
G	Electrogalvanised

Master data

Item number	1371207
Type	705 D M6
Description 1	Distance saddle
Description 2	with threaded connection M6
Manufacturer	OBO
Dimension	13-20mm
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	50
Unit of quantity	Piece
Weight	3.73 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0829 kg CO2e / 1 Piece


Technical data sheet

Screw-in spacer clip 705, double

Item number: 1371207



Dimensions

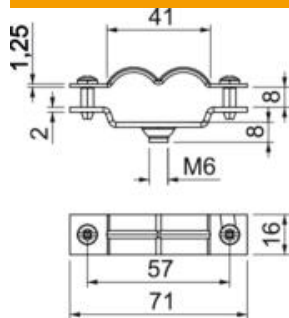

Dimension A	71 mm
Dimension B	57 mm
Dimension D	20 mm
Dimension d min.	20 mm
Dimension m (mm)	20

Technical data

Version for	Closed
Fastening type	Screw hole
Halogen-free	no
Plastic-covered	no
Hole size	M6
Material thickness	1.25 mm
ROHS-conformant	yes
Bolt	M5 x 14
Clamping range D, max.	20 mm
Clamping range D, min.	13 mm
UV-resistant	yes