

Technical data sheet

Carrier screw clamp

Item number: 1408534



Carrier screw clamp for mounting components on steel profiles. With M6 threaded hole for threaded rods. Fastened to steel girder or flat iron with a pressure trough and M8 hexagon screw, wrench size 13 mm.



St

Steel

G

Electrogalvanised

Master data

Item number	1408534
Type	339 2
Description 1	Carrier screw clamp
Description 2	heavyweight design
Manufacturer	OBO
Dimension	6-34mm
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	5
Unit of quantity	Pair
Weight	37 kg
Weight unit	kg/100 pairs
CO2 Footprint (GWP) Cradle-to-Gate	0,8912 kg CO2e / 2 Piece

Technical data sheet


Carrier screw clamp

Item number: 1408534



Dimensions

M8x40

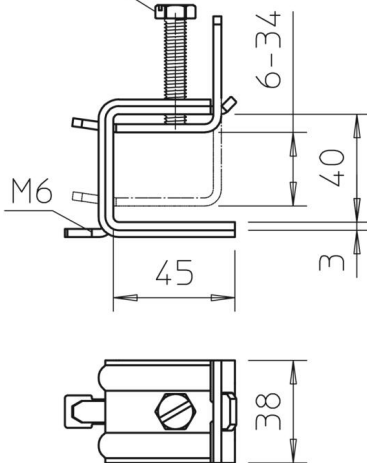

Technical data

Fastening type	Bolts
Flange thickness F max.	34 mm
Flange thickness F min.	6 mm
ROHS-conformant	yes
Hinge, adjustable	no
Hinged	no