


# Technical data sheet

## Strain relief clip 7908

Item number: 1442015

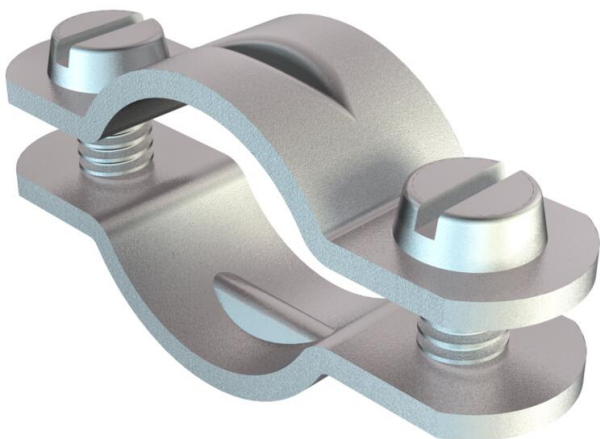

Strain relief clip 11 mm



- St Steel
- G Electrogalvanised

| Master data                        |                            |
|------------------------------------|----------------------------|
| Item number                        | 1442015                    |
| Type                               | 7908 11 G                  |
| Description 1                      | Strain relief clip         |
| Manufacturer                       | OBO                        |
| Dimension                          | 11mm                       |
| Material                           | Steel                      |
| Surface                            | Electrogalvanised          |
| Surface standard                   | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit                | 100                        |
| Unit of quantity                   | Piece                      |
| Weight                             | 0.433 kg                   |
| Weight unit                        | kg/100 pc.                 |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0218 kg CO2e / 1 Piece   |

| Dimensions |  |
|------------|--|
|            |  |

# Technical data sheet

## Strain relief clip 7908

Item number: 1442015



### Technical data

|                                  |            |
|----------------------------------|------------|
| Distance to the wall             | no         |
| Number of cables/pipes           | 1          |
| Version for                      | Two-lobe   |
| Fastening type                   | Screw hole |
| For diameter                     | 11         |
| Suitable in fire protection area | no         |
| Halogen-free                     | yes        |
| Plastic-covered                  | no         |
| Material thickness               | 1 mm       |
| Nominal diameter                 | 11 mm      |
| ROHS-conformant                  | Exempt     |
| Clamping range D, max.           | 11 mm      |
| Clamping range D, min.           | 11 mm      |
| UV-resistant                     | yes        |