


Technical data sheet

Strain relief clip 7909

Item number: 1443011

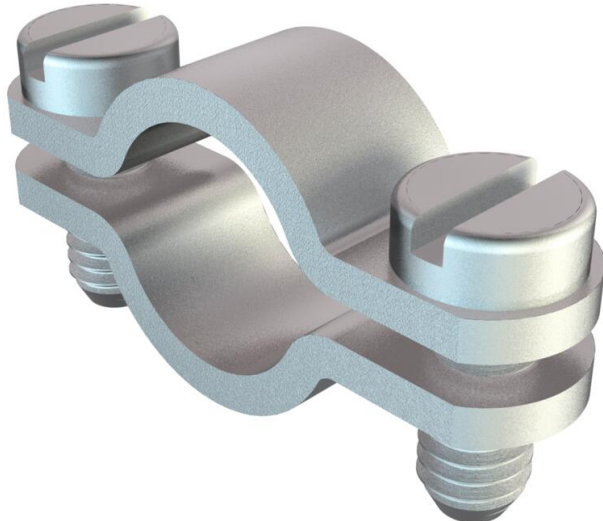

Fastening clip for strain relief of cables



St	Steel
G	Electrogalvanised

Master data

Item number	1443011
Type	7909 6 G
Description 1	Strain relief clip
Manufacturer	OBO
Dimension	6mm
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.198 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0071 kg CO2e / 1 Piece


Technical data sheet

Strain relief clip 7909

Item number: 1443011



Dimensions

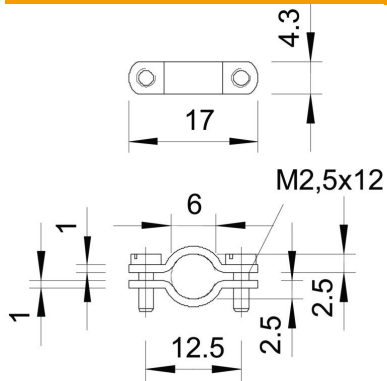

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	6
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Material thickness	1 mm
Nominal diameter	6 mm
ROHS-conformant	yes
Clamping range D, max.	6 mm
Clamping range D, min.	6 mm
UV-resistant	yes