


Technical data sheet

Universal cover

Item number: 2003748



Universal cover for flush-mounted and cavity wall box. With drill holes, hole spacing 60 mm for all device boxes, retractable screws. Roughened surface.

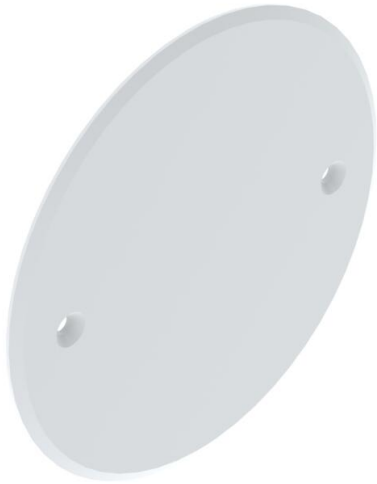

PC/
ABS

Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	2003748
Type	ZA 60-D
Description 1	Universal cover
Available from	01.10.2021
Manufacturer	OBO
Dimension	Ø84mm
Colour	White
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	25
Unit of quantity	Piece
Weight	0.85 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0445 kg CO2e / 1 Piece


Technical data sheet

Universal cover

Item number: 2003748



Dimensions

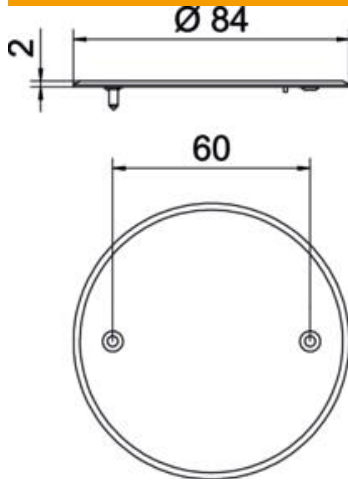

Height	1.8 mm
--------	--------

Technical data

Fastening type	Screws ,
Flame-resistant	Acc. to VDE 0471/IEC 60695-2-11, test temperature 850°C
Shape	Round
Halogen-free	yes
With bolts	no
ROHS-conformant	yes