

 

Technical data sheet

Cover, double, rectangular

Item number: 2003823



Rectangular cover for double flush-mounted and cavity wall box. With drill holes, retractable screws.

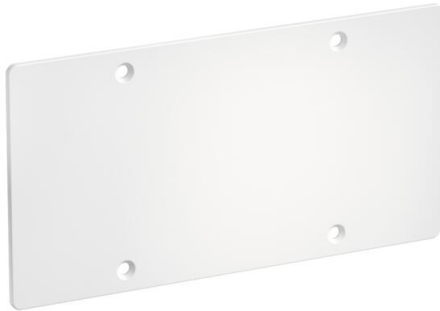

Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	2003823
Type	ZA 60-DV
Description 1	UP/HW cover
Description 2	double combination
Available from	01.10.2021
Manufacturer	OBO
Dimension	145x75x2
Colour	White
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	5
Unit of quantity	Piece
Weight	1.78 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0915 kg CO2e / 1 Piece


Technical data sheet

Cover, double, rectangular

Item number: 2003823



Dimensions

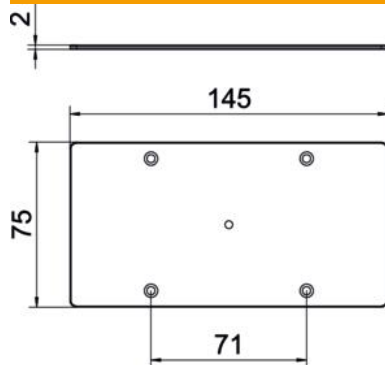

Length	145 mm
Width	75 mm
Height	2 mm

Technical data

Fastening type	Screw-on lid
Flame-resistant	Acc. to VDE 0471/IEC 60695-2-11, test temperature 850°C
Shape	Rectangular
Halogen-free	yes
With bolts	no
ROHS-conformant	yes