


Technical data sheet

Inner fitting, cover cavity wall device box

Item number: 2003848



Inner fitting cover for cavity wall device box, to screw on.

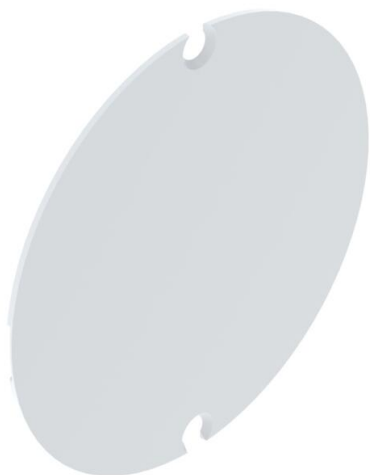

Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	2003848
Type	ZH 60-ID
Description 1	Inner fitting cover
Description 2	for cavity wall device box
Available from	01.10.2021
Manufacturer	OBO
Dimension	Ø65mm
Colour	White
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.13 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0574 kg CO2e / 1 Piece

Technical data sheet

Inner fitting, cover cavity wall device box


Item number: 2003848



Dimensions



Height 1 mm

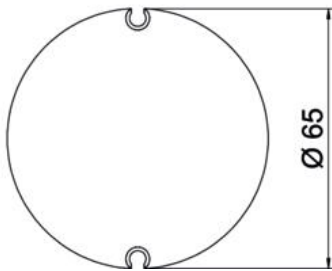

Technical data

Version, concealed and cavity wall cover	Internal
Fastening type	Screws ,
Flame-resistant	Acc. to VDE 0471/IEC 60695-2-11, test temperature 850°C
Shape	Round
Halogen-free	yes
With bolts	no
ROHS-conformant	yes