

Technical data sheet

Pluggable cover, equipped, OBO GST18

Item number: 2006044



Pluggable cover for the closing of junction boxes, equipped with 2 Wieland GST18 plug systems, prewired with lever plug-in connector With quick lock in cover, sealable. Halogen-free material, UV-resistant Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection class IP30.



PP Polypropylene

Master data

Item number	2006044
Type	D01 2x3p WD(1+1)
Description 1	Plug-in cover
Description 2	for junction box, equipped
Manufacturer	OBO
Dimension	150x116x60
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	1
Unit of quantity	Piece
Weight	14.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3127 kg CO2e / 1 Piece


Technical data sheet

Pluggable cover, equipped, OBO GST18

Item number: 2006044



Dimensions

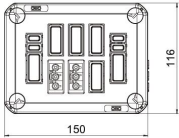

Length	150 mm
Width	116 mm
Height	60 mm

Technical data

Number of 3-pole sockets	2
Number of 4-pole sockets	0
Number of 5-pole sockets	0
Version, concealed and cavity wall cover	Suitable for snap-in connector (manufacturer specific)
Fastening type	Screw fastening
Shape	Rectangular
Halogen-free	yes
Protection rating	IP30