

Technical data sheet

Pluggable cover, equipped, WAGO WINSTA

Item number: 2006087



Pluggable cover for the closing of junction boxes, equipped with 2 Wago WINSTA plug systems, 5-pole, prewired with lever plug-in connectors. With quick lock-in cover, sealable. Halogen-free material, UV-resistant. Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection rating IP30.



Master data

Item number	2006087
Type	D02 2x5p WG
Description 1	Plug-in cover
Description 2	for junction box, equipped
Manufacturer	OBO
Dimension	150x116x60
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	1
Unit of quantity	Piece
Weight	17.8 kg
Weight unit	kg/100 pc.


Technical data sheet

Pluggable cover, equipped, WAGO WINSTA

Item number: 2006087



Dimensions

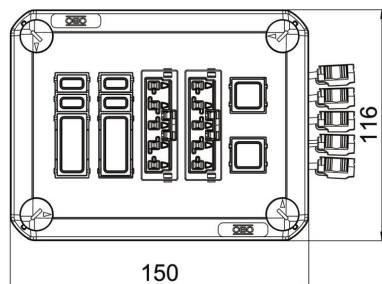

Length	150 mm
Width	116 mm
Height	60 mm

Technical data

Number of 3-pole sockets	0
Number of 4-pole sockets	0
Version, concealed and cavity wall cover	Suitable for snap-in connector (manufacturer specific)
Fastening type	Screw fastening
Shape	Rectangular
Protection rating	IP30