


Technical data sheet

Mounting and fastening plate T350

Item number: 2007884

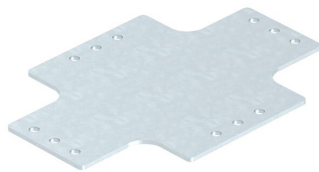

This mounting and fastening plate gives the options for variable fixing of external components in the junction box. It consists of strip-galvanised sheet steel of a material thickness of 2 mm.

The appropriate fastening holes are drilled into the steel plate for the component that needs to be fixed. Then, the products can be attached onto the sheet with cable ties, screws or similar fastening materials.

Using the screws included in the scope of the delivery, the mounting fastening plate can now be fixed in the appropriate T series (T 160) junction box.



St	Steel
FS	Strip galvanised

Master data

Item number	2007884
Type	MBP T160
Description 1	Mounting fastening plate
Description 2	incl. fastening screws
Manufacturer	OBO
Dimension	140x100x2
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	15.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,5665 kg CO2e / 1 Piece


Technical data sheet

Mounting and fastening plate T350

Item number: 2007884



Dimensions

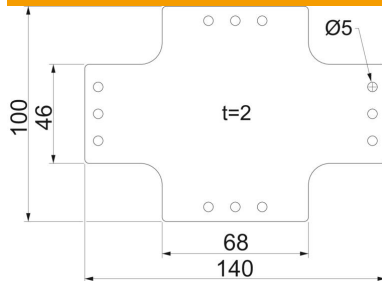

Width	140 mm
Height	100 mm
Dimension B	100 mm
Dimension B1	46 mm
Dimension L	140 mm
Dimension L1	68 mm

Technical data

Material thickness	2 mm
With perforation	yes