

Technical data sheet

Plug-in seal EDK light grey

Item number: 2011638



The plug-in seal can be cut back to suit the relevant cable diameter.



TPE Thermoplastic elastomer

Master data		
Item number	2011638	
Type	EDK 25 LGR	
Description 1	Plug-in seal	
Description 2	for cable	
Manufacturer	OBO	
Dimension	Ø25/5-20	
Colour	Light grey; RAL 7035	
Material	Thermoplastic elastomer	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	0.214 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0072 kg CO2e / 1 Piece	


Technical data sheet

Plug-in seal EDK light grey

Item number: 2011638



Dimensions

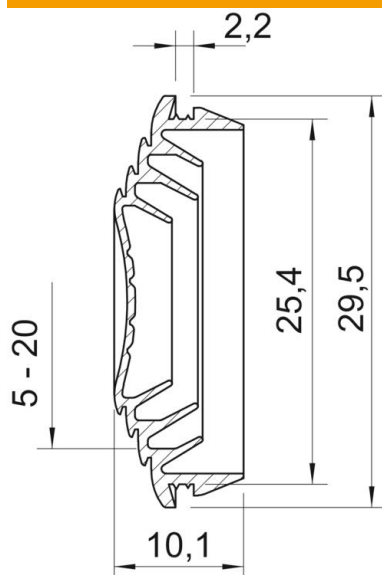

Dimension A	2.2 mm
Dimension D1	29.5 mm
Dimension D2	25.4 mm
Dimension D3	5 mm
Dimension D4	14 mm
Dimension D5	15 mm
Dimension D6	18
Dimension D7	19
Dimension D8	20
Dimension L	10.1 mm

Technical data

Version for	Cuttable
for diameter, max.	20 mm
for diameter, min.	5 mm
for wall thickness, max.	2.2 mm
for wall thickness, min.	2.2 mm
Size	M25
Halogen-free	yes
Nominal diameter	25 mm
Protection rating	IP55