

Technical data sheet

EDS plug-in seal, light black

Item number: 2012340



The push-in nipple can be cut back to suit the relevant cable diameter.



M

HALOGEN FREE

CE UK CA

IP 54

M

TPE

Thermoplastic elastomer

Master data	
Item number	2012340
Type	EDS M20 SW
Description 1	Plug-in seal
Description 2	for 3-mm wall thickness
Manufacturer	OBO
Dimension	M20
Colour	Black
Material	Thermoplastic elastomer
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.125 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0078 kg CO2e / 1 Piece


Technical data sheet

EDS plug-in seal, light black

Item number: 2012340



Dimensions

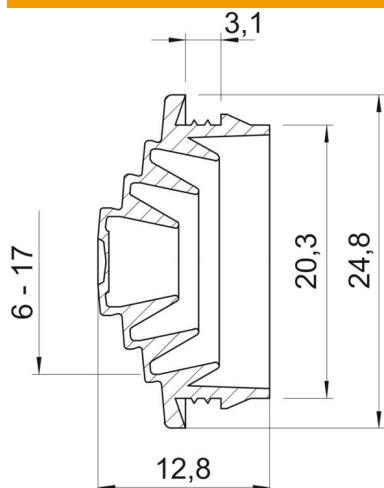

Dimension A	3.1 mm
Dimension D1	24.8 mm
Dimension D2	20.3 mm
Dimension D3	6 mm
Dimension D4	10 mm
Dimension D5	15 mm
Dimension D6	17
Dimension L	12.8 mm
Dimension t	3.1 mm

Technical data

Version for	Cuttable
Flame-resistant	acc. to VDE 0471/DIN 695 Part 2-1, test temperature 650°C
for diameter, max.	17 mm
for diameter, min.	0 mm
for wall thickness, max.	3.1 mm
for wall thickness, min.	2.5 mm
Size	M20
Halogen-free	yes
Nominal diameter	20 mm
ROHS-conformant	yes
Protection rating	IP54