

Technical data sheet

Plug-in seal EDVS, light grey

Item number: 2012375



The push-in nipple can be cut back to suit the relevant cable diameter.



M

HALOGEN FREE

CE UK CA

IP 54

M

EVA

Ethylene vinyl acetate

Master data		
Item number	2012375	
Type	EDVS M20 LGR	
Description 1	Plug-in seal	
Manufacturer	OBO	
Dimension	M20	
Colour	Light grey; RAL 7035	
Material	Ethylene vinyl acetate	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	0.117 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0103 kg CO2e / 1 Piece	


Technical data sheet

Plug-in seal EDVS, light grey

Item number: 2012375



Dimensions

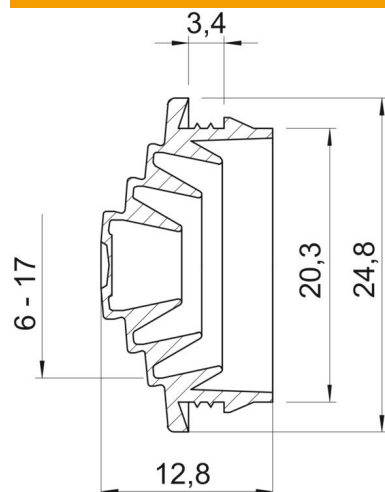

Dimension A	3.4 mm
Dimension D1	24.8 mm
Dimension D2	20.3 mm
Dimension D3	6 mm
Dimension D4	10 mm
Dimension D5	15 mm
Dimension D6	17
Dimension L	12.8 mm
Dimension t	3.4 mm

Technical data

Version for	Cuttable
Flame-resistant	acc. to VDE 0471/DIN 695 Part 2-1, test temperature 650°C
for diameter, max.	17 mm
for diameter, min.	0 mm
Size	M20
Halogen-free	yes
Nominal diameter	20 mm
ROHS-conformant	yes
Protection rating	IP54