

Technical data sheet

Flat cable threaded connection, PG thread rectangular version, stone grey

Item number: 2012774



Flat-cable entry, choke-nipple design with PG connecting thread to DIN 40430, protection rating IP31, with pre-mounted support sealing ring 107/F.



PE Polyethylene

Master data

Item number	2012774
Type	106 FL 29 14 40
Description 1	Flat cable threaded connection
Manufacturer	OBO
Dimension	PG29
Colour	Stone grey; RAL 7030
Material	Polyethylene
Smallest sales unit	15
Unit of quantity	Piece
Weight	3.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1102 kg CO2e / 1 Piece


Technical data sheet

Flat cable threaded connection, PG thread rectangular version, stone grey

Item number: 2012774



Dimensions

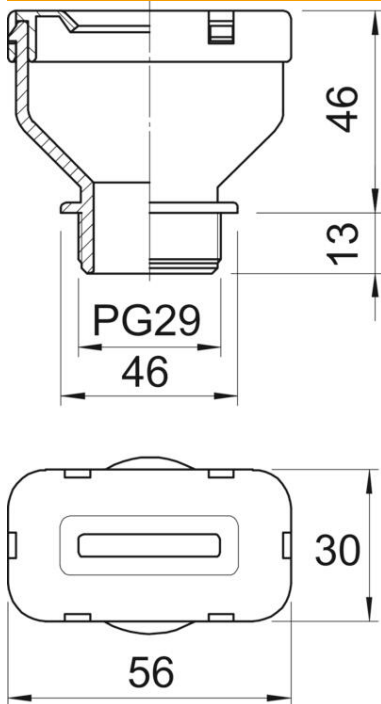

Dimension A	30 mm
Dimension B	56 mm
Dimension D	46 mm
Dimension G	PG29 mm
Dimension L	59 mm
Dimension L1	13 mm
Dimension L2	46 mm

Technical data

Type of seal	Sealing ring
Bend protection	no
Flat cable/width, max.	40 mm
Flat cable/width, min.	37 mm
Flat cables/thickness, max.	14 mm
Flat cables/thickness, min.	11 mm
Flat cable gland	yes
For Ex zone	Without
Thread	Pg 29
Thread type	PG
Fibre-glass reinforced	no
Sealing insert, multiple	no
With locknut	no
ROHS-conformant	yes
Impact-resistant	no
Protection rating	IP31
Strain relief option	no