

Technical data sheet

Flat cable threaded connection, metric thread M25, stone grey

Item number: 2013006



Flat-cable entry, choke-nipple design with metric connecting thread to IEC 432, protection rating IP31, with pre-mounted support sealing ring 107/F.



Master data

Item number	2013006
Type	106 FL M25 6 30
Description 1	Flat cable threaded connection
Manufacturer	OBO
Dimension	M25
Colour	Stone grey; RAL 7030
Material	Polyethylene
Smallest sales unit	25
Unit of quantity	Piece
Weight	2.63 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0876 kg CO2e / 1 Piece


Technical data sheet

Flat cable threaded connection, metric thread M25, stone grey

Item number: 2013006



Dimensions

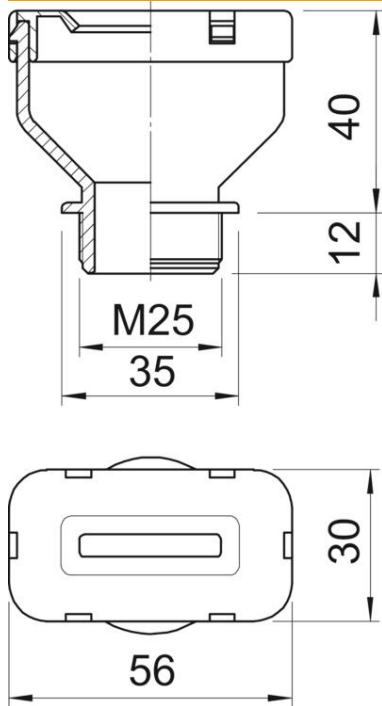

Dimension A	30 mm
Dimension B	56 mm
Dimension D	35 mm
Dimension G	M25 mm
Dimension L	52 mm
Dimension L1	12 mm
Dimension L2	40 mm

Technical data

Type of seal	Sealing ring
Version for	Straight
Bend protection	yes
explosion-proof	no
Flat cable/width, max.	30 mm
Flat cable/width, min.	27 mm
Flat cables/thickness, max.	6 mm
Flat cables/thickness, min.	4 mm
Flat cable gland	yes
For Ex zone	Without
Thread	M25
Thread type	Metric
Fibre-glass reinforced	no
Sealing insert, multiple	no
With locknut	no
ROHS-conformant	yes
Impact-resistant	no
Protection rating	IP31
Strain relief option	no