

Technical data sheet

Cable connection sleeve

Item number: 2022060



Protection rating IP54, nominal voltage 660 V. VDE specifications state that connection sleeves are only intended for local routing.
117/2.5 VDE / PG 16: nominal cross-section 2.5 mm², with 5-pole terminal insert 2.5 mm² and cable entries with strain relief for cable diameter 9–14 mm.
117/6 VDE / PG 21: nominal cross-section 6 mm², with 5-pole terminal insert 6 mm² and cable entries with strain relief for cable diameter 12–18 mm.

117/6 VDE: Nennquerschnitt mm², mit 5poligem Klemmeinsatz 6 mm² und Kabeleinführungen mit Zugentlastung Pg 21 für Kabeldurchmesser 12-18 mm 5-pole terminal insert 6 mm²



PS Polystyrene

Master data

Item number	2022060
Type	117 5x6
Description 1	Cable connection sleeve
Manufacturer	OBO
Dimension	6mm2
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	5
Unit of quantity	Piece
Weight	8.306 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2342 kg CO2e / 1 Piece


Technical data sheet

Cable connection sleeve

Item number: 2022060



Dimensions

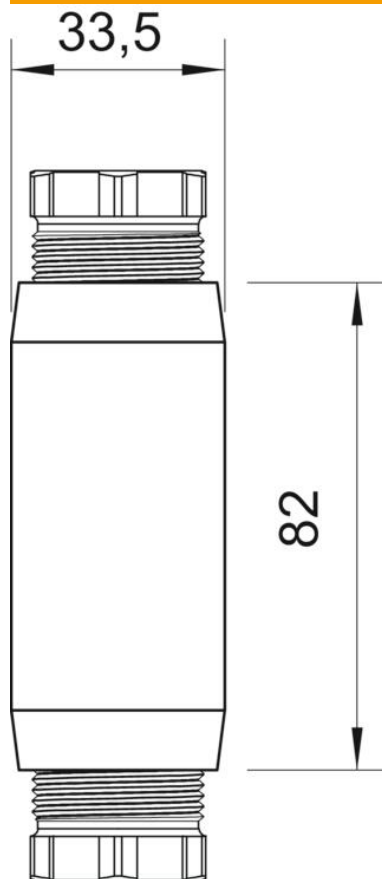

Dimension D	33.5 mm
Dimension L	82 mm

Technical data

Entries	Pg 21
Halogen-free	yes
Nominal voltage	660 V
ROHS-conformant	yes
Impact-resistant	yes
Protection rating	IP54