


Technical data sheet

Pressure screw, PG strain relief 107

Item number: 2023091

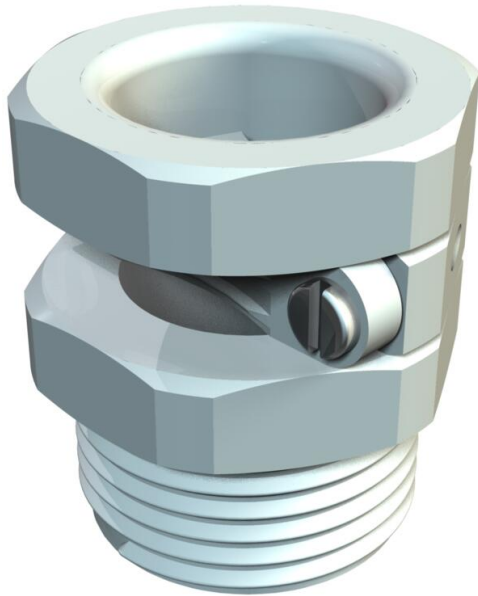

Pressure screw with transverse clip strain relief, electrogalvanised steel screws, PG thread to DIN 40430.

HALOGEN
FREE

Pg

PA

Polyamide

Master data

Item number	2023091
Type	107 Z PG 9 PA
Description 1	Pressure screw
Description 2	with strain relief
Manufacturer	OBO
Dimension	PG9
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0166 kg CO2e / 1 Piece


Technical data sheet

Pressure screw, PG strain relief 107

Item number: 2023091



Dimensions

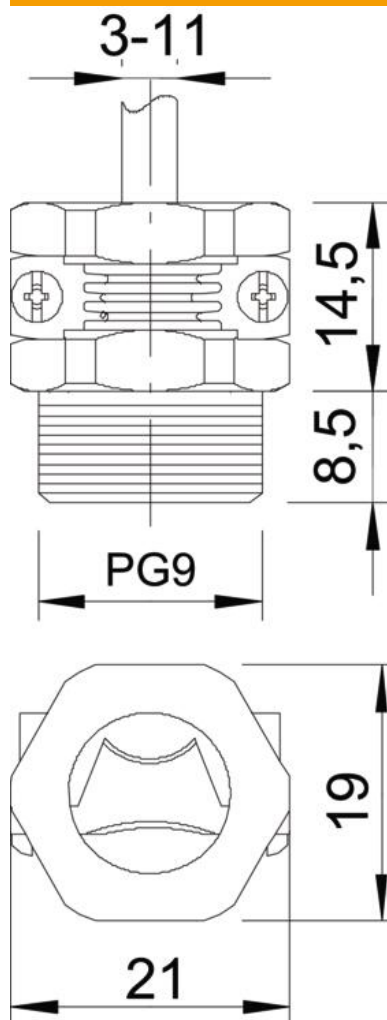

Dimension E	21 mm
Dimension L1	8.5 mm
Dimension L2	14.5 mm

Technical data

Thread type	PG
Nominal thread size	9
Thread increase	1.41 mm
Fibre-glass reinforced	no
Halogen-free	yes
ROHS-conformant	yes
Impact-resistant	no
WAF	19
Strain relief option	yes
Clamping range, max.	11.3 mm
Clamping range, min.	3.5 mm