

Technical data sheet

Screw plug, PG thread

Item number: 2033070



Screw plug in accordance with DIN 46320, with PG thread to DIN 40430.
Protection rating IP54, IP68 (5 bar/1h) possible in conjunction with sealing ring type 171.



PS Polystyrene

Master data

Item number	2033070
Type	108 PG 7
Description 1	Screw plug
Manufacturer	OBO
Dimension	PG7
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.056 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0035 kg CO2e / 1 Piece


Technical data sheet

Screw plug, PG thread

Item number: 2033070



Dimensions

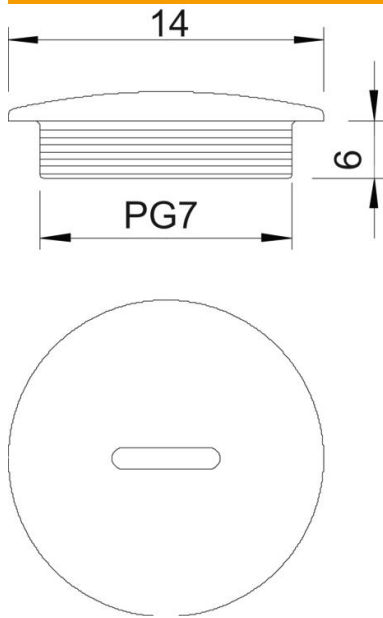

Dimension D	14 mm
Dimension L	6 mm

Technical data

explosion-proof	no
For Ex zone gas	Without
For Ex zone dust	Without
Thread	Pg 7
Thread type	PG
Nominal thread size metric/PG	7
Thread increase	1.27 mm
Fibre-glass reinforced	no
Halogen-free	yes
Unstable torque	1.3 Nm
ROHS-conformant	yes
Impact-resistant	yes
Protection rating	IP54