

Technical data sheet

Aluminium pipe, without thread

Item number: 2046002



Electrical installation pipe without threaded ends to EN 61386-1 for mechanical protection of cables. With burr-free inner wall.



Alu Aluminium

Master data

Item number	2046002
Type	S16W ALU
Description 1	Aluminium conduit
Description 2	without thread
Manufacturer	OBO
Dimension	Ø16, 3000mm
Material	Aluminium
Smallest sales unit	30
Unit of quantity	Metre
Weight	15.065 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,8975 kg CO2e / 1 Meter


Technical data sheet

Aluminium pipe, without thread


Item number: 2046002



Dimensions

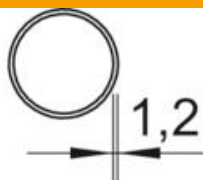

Length	3,000 mm
Dimension D	16 mm
Dimension L	3,000 mm
Dimension m (mm)	M16
Dimension t	1.2 mm

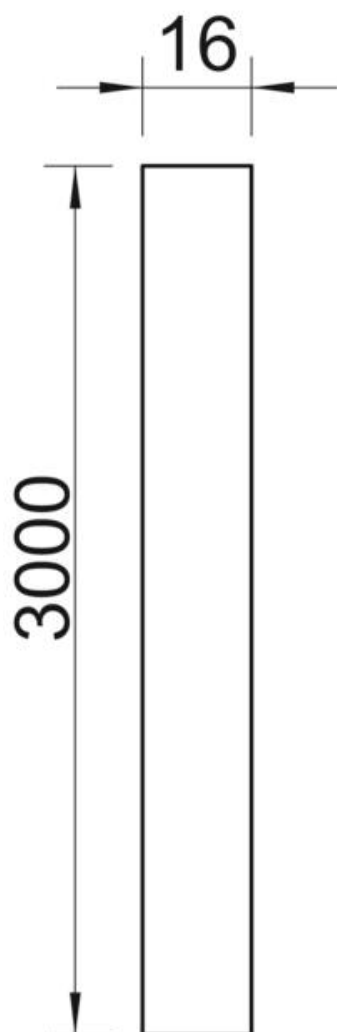

Technical data sheet

Aluminium pipe, without thread

Item number: 2046002



Technical data

Surface-mounted	yes
Pipe version	Rigid without thread
Concrete installation	no
Bending behaviour	rigid
Pressure resistance	Heavy (1,250 N)
Use temperature, max.	+ 250 °C
Use temperature, min.	- 45 °C
Cavity wall installation	yes
Installation on wood	yes
Installation in the earth	no
Installation outdoors	yes
Classification code	44561
Machines and system installation	yes
With sleeve	no
Brushed surface	no
Polished surface	no
ROHS-conformant	yes
Impact resistance	Heavy (2.0 kg/300 mm)
Permitted temperature range, max.	250 °C
Permitted temperature range, min.	-45 °C
Underfloor installation (bitumen, hot asphalt)	yes
Underfloor installation (screed)	yes
Concealed	no