

Technical data sheet

Armoured steel pipe without thread, black

Item number: 2046565



Electrical installation pipe without threaded ends according to EN 61386-1 for mechanical protection of cables. With burr-free inner wall.



St	Steel
PE50	PES50 - Polyester/epoxy

Master data

Item number	2046565
Type	S16W SW
Description 1	Plug-in conduit
Description 2	without thread
Manufacturer	OBO
Dimension	Ø16, 3000mm
Colour	Jet black; RAL 9005
Material	Steel
Surface	PES50 - Polyester/epoxy
Surface standard	
Smallest sales unit	30
Unit of quantity	Metre
Weight	37 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,769 kg CO2e / 1 Meter


Technical data sheet

Armoured steel pipe without thread, black

Item number: 2046565



Dimensions

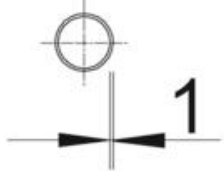

Length	3,000 mm
Dimension D	16 mm
Dimension L	3,000 mm
Dimension m (mm)	M16
Dimension t	1 mm



3000

Technical data sheet

Armoured steel pipe without thread, black

Item number: 2046565



Technical data

Surface-mounted	yes
Pipe version	Rigid without thread
Concrete installation	yes
Bending behaviour	rigid
Pressure resistance	Heavy (1,250 N)
Use temperature, max.	+ 250 °C
Use temperature, min.	- 45 °C
Cavity wall installation	yes
Installation on wood	yes
Installation in the earth	no
Installation outdoors	no
Classification code	44561
Machines and system installation	yes
With sleeve	no
Brushed surface	no
Polished surface	no
ROHS-conformant	yes
Impact resistance	Heavy (2.0 kg/300 mm)
Permitted temperature range, max.	250 °C
Permitted temperature range, min.	-45 °C
Underfloor installation (bitumen, hot asphalt)	yes
Underfloor installation (screed)	yes
Concealed	yes