

Technical data sheet

Electrogalvanised steel sleeve, with thread

Item number: 2046875



Accessory part: coupling with thread according to EN 60423 to connect electrical installation pipes and 90° bends.



St	Steel
G	Electrogalvanised

Master data

Item number	2046875
Type	SVM16W G
Description 1	Conduit threaded coupler
Description 2	with thread
Manufacturer	OBO
Dimension	M16x1,5
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	25
Unit of quantity	Piece
Weight	2.11 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1494 kg CO2e / 1 Piece


Technical data sheet

Electrogalvanised steel sleeve, with thread

Item number: 2046875



Dimensions

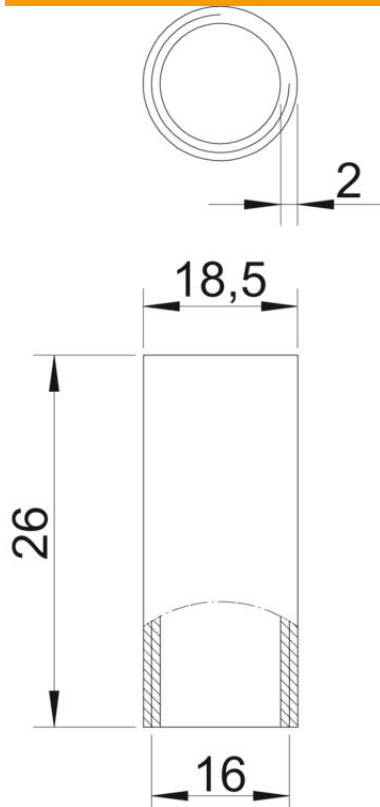

Dimension D	18.5 mm
Dimension d	16 mm
Dimension L	26 mm
Dimension m (mm)	M16
Dimension t	2 mm

Technical data

Version for	Thread
for pipe diameter	16 mm
Thread	M16x1,5
Size	16
Halogen-free	no
With inspection opening and lid	no
Brushed surface	no
Polished surface	no
ROHS-conformant	yes
Permitted temperature range, max.	400 °C
Permitted temperature range, min.	-45 °C
Two-part	no