

Technical data sheet

Plastic pipe, rigid, halogen-free

Item number: 2047720



Electrical installation pipe to EN 61386-1, made of halogen-free plastic to EN 50642, for the mechanical protection of cables.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	2047720
Type	KH16 LGR
Description 1	Plastic armoured pipe
Description 2	halogen-free
Manufacturer	OBO
Dimension	Ø16, 3000mm
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	57
Unit of quantity	Metre
Weight	8.6 kg
Weight unit	kg/100 m

Technical data sheet


Plastic pipe, rigid, halogen-free

Item number: 2047720



Dimensions

Length	3,000 mm
Dimension D	16 mm
Dimension L	3,000 mm
Dimension m (mm)	M16
Dimension t	1.6 mm

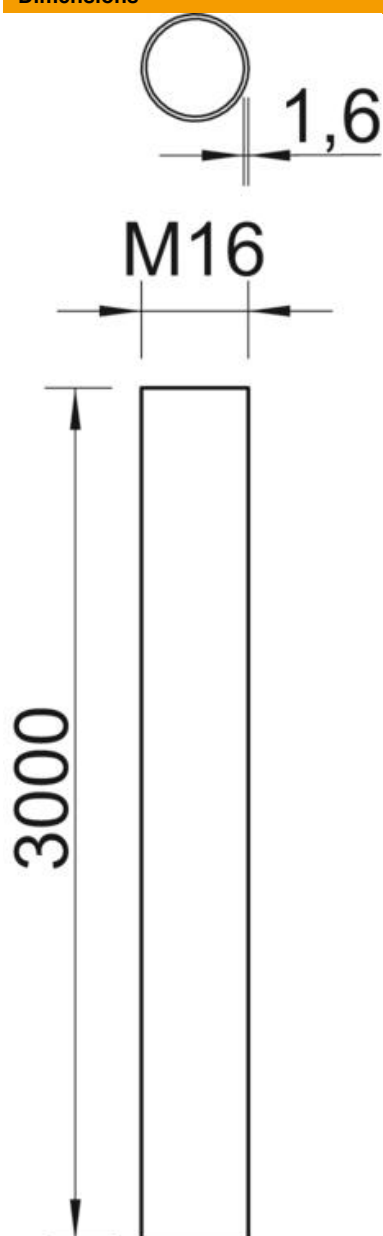

Technical data sheet

Plastic pipe, rigid, halogen-free

Item number: 2047720



Technical data

Bending behaviour	rigid
Pressure resistance	Heavy (1,250 N)
Use temperature, max.	+ 90 °C
Use temperature, min.	- 15 °C
Size	M16
Halogen-free	yes
Classification code	0
ROHS-conformant	yes
Impact resistance	Heavy (2.0 kg/300 mm)