


Technical data sheet

Neutral conductor terminal, with screw contacts, 12 terminals

Item number: 2054086

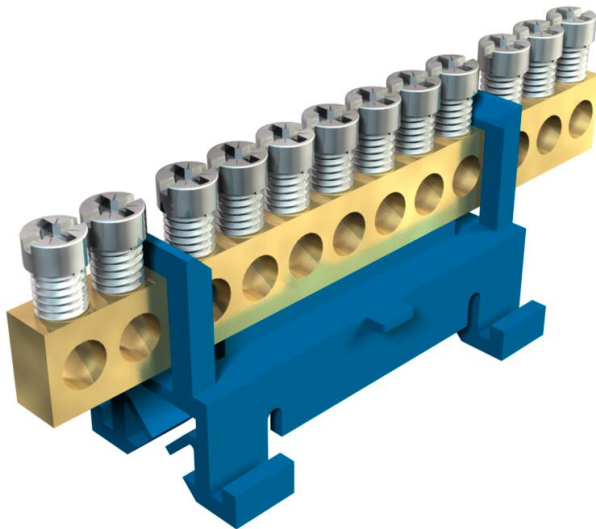

Neutral conductor connection terminal with 12 terminals up to 16 mm².

Clamping rail, brass, steel screws, electrogalvanised and transparently passivated, for snapping onto 35 mm hat rails to DIN EN 60715 - previously DIN EN 50022 - (transverse) or flat rails 10 x 2-2.5 mm (lengthwise).



PA Polyamide

Master data

Item number	2054086
Type	60 N 12x16 BL
Description 1	Neutral conductor clamp
Manufacturer	OBO
Dimension	12x16mm ²
Colour	Blue
Material	Polyamide
Smallest sales unit	10
Unit of quantity	Piece
Weight	4.2 kg
Weight unit	kg/100 pc.


Technical data sheet

Neutral conductor terminal, with screw contacts, 12 terminals

Item number: 2054086



Dimensions

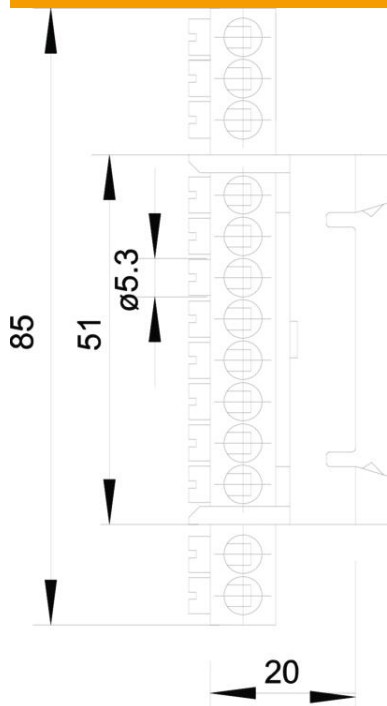

Length	85 mm
Height	20 mm

Technical data

Closing plate required	no
No. of terminals	12
Explosion-tested version	no
Suitable for flexible conductors	no
Suitable for solid conductors	no
Suitable for multi-wire conductors	no
Mounting type	DIN rail 35 mm
Nominal cross-section, max.	16 mm ²
Nominal cross-section, min.	10 mm ²
Pole number	12
Cross-section	12 terminals to 16 mm ² mm ²