

Technical data sheet

Reduction, PG thread

Item number: 2089025



Reduction (Part H) to DIN 46320, with Pg thread to DIN 40430, as a transition from a PG thread hole to a smaller cable gland.

* Prices according to DEL notation.



Brass



Nickel-plated

Master data

Item number	2089025
Type	167 R MS PG9-7
Description 1	Reduction
Manufacturer	OBO
Dimension	PG9-PG7
Material	Brass
Surface	Nickel-plated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	0.43 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0119 kg CO2e / 1 Piece


Technical data sheet

Reduction, PG thread

Item number: 2089025



Dimensions

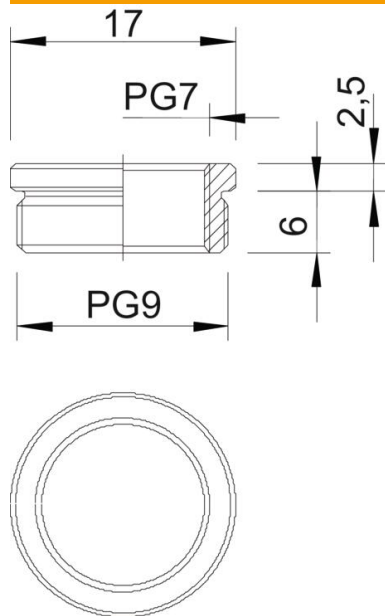

Dimension D	17 mm
Dimension L1	6 mm
Dimension L2	2.5 mm

Technical data

explosion-proof	no
Thread type: External thread	PG
Thread type: Internal thread	PG
Thread length	6 mm
Thread dimension, PG, external	9
Thread dimension, PG, internal	7
Nickel-plated	yes