

Technical data sheet

Screw plug, metric thread

Item number: 2090650



Metal screw plug with integrated sealing ring To close unused threaded openings, e.g. in housings or junction and branch boxes. With metric thread to DIN EN 60423 or ISO 68. Protection class IP 68 (5 bar/1 h).



Brass



Nickel-plated

Master data

Item number	2090650
Type	168 MS M12 + O
Description 1	Screw plug
Description 2	with O ring
Manufacturer	OBO
Dimension	Ø16x8
Material	Brass
Surface	Nickel-plated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.005 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0003 kg CO2e / 1 Piece


Technical data sheet

Screw plug, metric thread

Item number: 2090650



Dimensions

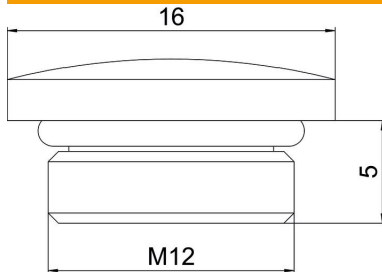

Length	16 mm
Width	16 mm
Height	8 mm
Dimension D	16 mm
Dimension L	5 mm

Technical data

explosion-proof	no
For Ex zone gas	Without
For Ex zone dust	Without
Thread	M12 x 1,5
Thread type	Metric
Nominal thread size metric/PG	12
Thread increase	1.5 mm
Fibre-glass reinforced	no
Halogen-free	yes
Impact-resistant	no
Protection rating	IP68