

Technical data sheet

Locknut, metric thread

Item number: 2091607



Locknut to DIN 46319 with metric thread IEC 423.

* Prices according to DEL notation.



Brass



Nickel-plated

Master data

Item number	2091607
Type	169 MS M12
Description 1	Locknut
Manufacturer	OBO
Dimension	M12
Material	Brass
Surface	Nickel-plated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.22 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0059 kg CO2e / 1 Piece


Technical data sheet

Locknut, metric thread

Item number: 2091607



Dimensions

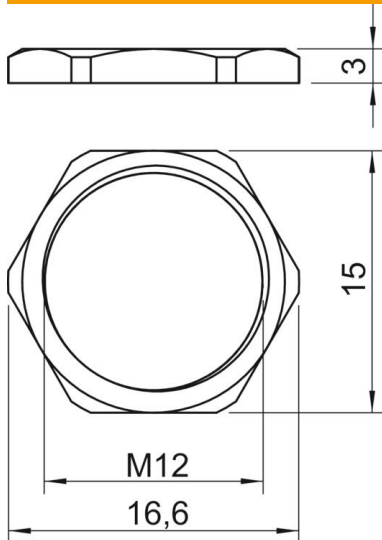

Dimension E	16.6 mm
Dimension L	3 mm

Technical data

Thread	M12 x 1,5
Thread type	Metric
Nominal thread size metric/PG	12
Fibre-glass reinforced	no
Halogen-free	no
Impact-resistant	no
WAF	15