


# Technical data sheet

## Grip ISO clip, single

Item number: 2105012

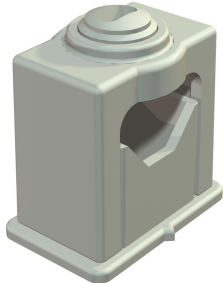

Solid cable fastening through clamping screws, with adhesive base, slot and for screwing to M6 thread.

Use the Impu-Fix ribbon conductor quick adhesive, type 509, to stick the polystyrene clips to masonry and concrete.



PS

Polystyrene

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 2105012                  |
| Type                               | 3040 LGR                 |
| Description 1                      | Grip ISO clip            |
| Manufacturer                       | OBO                      |
| Dimension                          | 6-16mm                   |
| Colour                             | Light grey; RAL 7035     |
| Material                           | Polystyrene              |
| Smallest sales unit                | 100                      |
| Unit of quantity                   | Piece                    |
| Weight                             | 0.6 kg                   |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0227 kg CO2e / 1 Piece |


# Technical data sheet

## Grip ISO clip, single

Item number: 2105012



### Dimensions

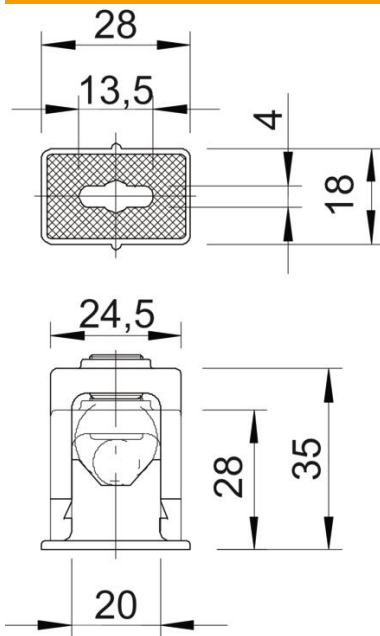

|                   |         |
|-------------------|---------|
| Dimension a       | 28 mm   |
| Dimension a1 (mm) | 13.5 mm |
| Dimension b       | 18 mm   |
| Dimension b1      | 4 mm    |
| Dimension c       | 24.5 mm |
| Dimension d       | 28 mm   |
| Dimension e       | 35 mm   |
| Dimension f       | 20 mm   |

### Technical data

|                        |            |
|------------------------|------------|
| Expandable             | no         |
| Number of cables/pipes | 1          |
| Fastening type         | Screw hole |
| Halogen-free           | yes        |
| Snap system            | yes        |
| ROHS-conformant        | yes        |
| Impact-resistant       | yes        |
| Clamping range D, max. | 16 mm      |
| Clamping range D, min. | 6 mm       |