

Technical data sheet

Pressure ISO clip 3050, double, light grey

Item number: 2115018



For two cables, with adhesive base, slot and for screwing to M6 thread.
Use the Impu-Fix ribbon conductor quick adhesive, type 509, to stick the polystyrene clips to masonry and concrete.



PS

Polystyrene

Master data

Item number	2115018
Type	3050 2 6-16
Description 1	Pressure ISO clip
Description 2	for 2 cables
Manufacturer	OBO
Dimension	6-16mm
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.044 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0346 kg CO2e / 1 Piece


Technical data sheet

Pressure ISO clip 3050, double, light grey

Item number: 2115018



Dimensions

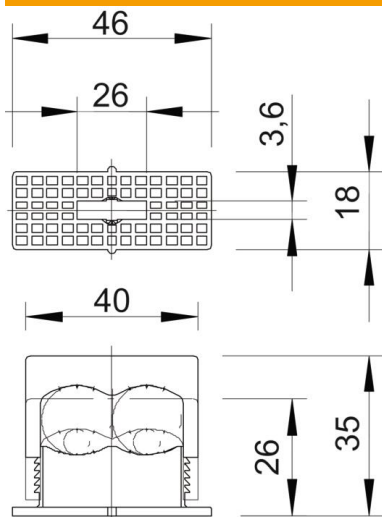

Dimension a	46 mm
Dimension a1 (mm)	26 mm
Dimension b	18 mm
Dimension b1	3.8 mm
Dimension c	40 mm
Dimension d	26 mm
Dimension e	35 mm

Technical data

Expandable	no
Number of cables/pipes	2
Fastening type	Screw hole
Halogen-free	yes
Snap system	yes
ROHS-conformant	yes
Impact-resistant	yes
Clamping range D, max.	16 mm
Clamping range D, min.	6 mm