


Technical data sheet

SOM clip, single

Item number: 2124149

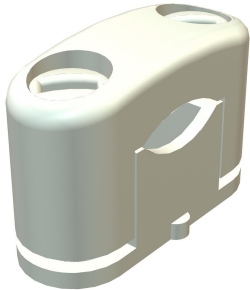

With plastic screws, so corrosion-protected, with slot for fastening with wood screws or 5 mm knock-in anchors.



PS

Polystyrene

Master data

Item number	2124149
Type	3079 LGR
Description 1	SOM clip
Manufacturer	OBO
Dimension	5-13mm
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	50
Unit of quantity	Piece
Weight	0.431 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0207 kg CO2e / 1 Piece


Technical data sheet

SOM clip, single

Item number: 2124149



Dimensions

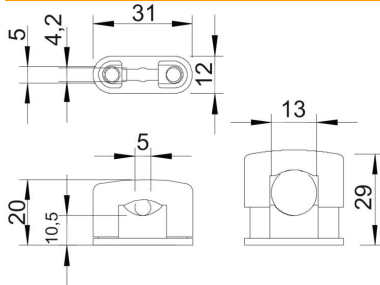

Dimension b	12 mm
Dimension b1	4.2 mm
Dimension b2	5 mm
Dimension d max.	13 mm
Dimension d min.	5 mm
Dimension H1	10.5 mm
Dimension H2	20 mm
Dimension H3	29 mm
Dimension L	31 mm

Technical data

Number of cables/pipes	1
Version for	Closed
Fastening type	Screw hole
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
ROHS-conformant	yes
Bolt	M5 x 14
Clamping range D, max.	14 mm
Clamping range D, min.	5 mm
UV-resistant	no