

Technical data sheet

proQuick clip, jet black

Item number: 2147340



Highly stressable clip for accepting plastic or metal electrical and sanitary pipes as well as the electrical installation pipe Quick pipe. Universal fastening options on walls, ceilings and steel constructions, both indoors and outdoors. Flexible clamping range of several millimetres. Toolless pipe mounting. Connectable to each other to $\varnothing$ 32 mm, also with the OBO Quick or Multi Quick clip. For variable distances and clip quantity mountable on a profile rail.



PA Polyamide

Master data

Item number	2147340
Type	PQ-20 SW
Description 1	proQuick clip
Manufacturer	OBO
Dimension	19,5-23,5mm
Colour	Jet black; RAL 9005
Material	Polyamide
Smallest sales unit	50
Unit of quantity	Piece
Weight	0.74 kg
Weight unit	kg/100 pc.


Technical data sheet

proQuick clip, jet black

Item number: 2147340



Dimensions

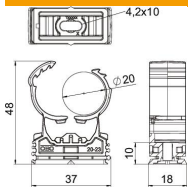

Technical data

Expandable	yes
Number of cables/pipes	1
Fastening type	Screw hole
Breaking load	0.8 kN
Closed	yes
Halogen-free	yes
With inlay	no
Nominal size	20-23
Snap system	yes
Pipe/cable diameter, max.	23.5 mm
Pipe/cable diameter, min.	19.5 mm
ROHS-conformant	yes
Clamping range D, max.	23.5 mm
Clamping range D, min.	19.5 mm
UV-resistant	yes