

Technical data sheet

Quick clip, light grey, OBO EcoLine

Item number: 2149018



Flush-mounted clip to accept metric steel armoured pipes and heavy-duty insulating pipes, as well as Quick Pipe electrical installation pipes. Universal fastening options on walls and ceilings, both in indoor and protected outdoor areas. With slot for side alignment during mounting with wood screw or knock-in anchor. Toolless pipe mounting. Can also be arranged with OBO Multi-Quick or proQuick clip. M16–M32 size can be screwed onto M6 thread. Recommended fastening spacing 50–60 cm, for max. extraction values F at a room temperature of 20 °C, see the table.



Polypropylene Eco

Master data

Item number	2149018
Type	2955 M25 ECO
Description 1	Quick clip
Available from	08.03.2026
Manufacturer	OBO
Dimension	M25
Colour	Light grey; RAL 7035
Material	Polypropylene Eco
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.439 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0086 kg CO2e / 1 Piece


Technical data sheet

Quick clip, light grey, OBO EcoLine

Item number: 2149018



Dimensions

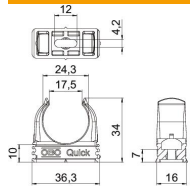

Dimension h 7 mm

Technical data

Expandable	yes
Number of cables/pipes	1
Fastening type	Screw hole
Closed	no
Halogen-free	yes
With inlay	no
ROHS-conformant	yes
Quick clip installation	Durchgangsloch, auf M6 Gewinde aufschraubbar
UV-resistant	no