


Technical data sheet

Quick pipe shears


Item number: 2153572



Shears for burr-free cutting of Quick Pipe electrical installation pipe Ø 16–32 mm.

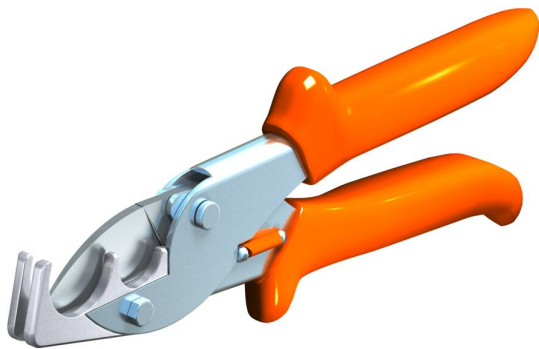

Master data		
Item number	2153572	
Type	SQ 1632	
Description 1	Quick channel shears	
Manufacturer	OBO	
Dimension	16-32mm	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	40 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0203 kg CO2e / 1 Piece	

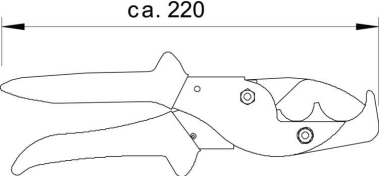Dimensions	
	
	

Technical data sheet

Quick pipe shears

Item number: 2153572



Technical data

Version for	Duct cutters
With wire cutter	no
ROHS-conformant	yes
Cutting area, max.	32 mm
Cutting area, min.	16 mm
Blade	Smooth
Direction scissors	double-sided
Material of the handle	Plastic