

Technical data sheet

Quick pipe T piece, pure white

Item number: 2153951



Fitting for plastic electrical installation pipes to create T branches. Suitable for Quick pipe pipes or corrugated pipes. Toolless closing and opening. Can be used in a temperature range of -25 to +60 °C.



PP Polypropylene

Master data

Item number	2153951
Type	3000 TMS M16 RW
Description 1	Quick pipe T piece
Manufacturer	OBO
Dimension	M16
Colour	Pure white; RAL 9010
Material	Polypropylene
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.798 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0784 kg CO2e / 1 Piece


Technical data sheet

Quick pipe T piece, pure white

Item number: 2153951



Dimensions

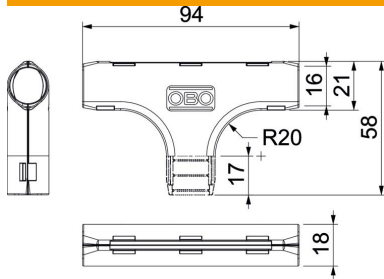

Dimension B	21 mm
Dimension B2	94 mm
Dimension d	16 mm
Dimension L	58 mm
Dimension L1	17 mm
Dimension R	20 mm

Technical data

Version for	Connector
Shape	T piece
Size	M16
Halogen-free	yes
With sleeve	no
Brushed surface	no
Polished surface	no
ROHS-conformant	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	0 °C